

UCCONNECT®

UC9500 High Density Fibre Suite



UC9500 Module MTP®/MPO Universal

- Recommended for method/polarity “B” 10G MPO channel using Type “B” MPO Trunk Cable to achieve simple migration to method/polarity “B” 40/100G MPO channel
- Available in Duplex LC
- Available in G657A, OM3 and OM4
- Utilises bend-insensitive fibre
- Plug & Play Installation
- Maximum Packing Density
- 100% Tested
- Utilised with UC9500 1U Distribution Panel, 4-Slot, Empty

Standards


ISO/IEC 11801, ANSI/TIA-568-C.3, IEC 61754-20, IEC 61754-7, RoHS Compliant

Specification


Item	Description	
Module Housing Material	Aluminum alloy, Thickness 0.8mm	
Module House Surface Finish	Watermark painted	
Module Housing Colour	BLACK	
Front Adaptor	Duplex LC with dust cap	
Rear Adaptor	MTP®/MPO with dust cap	
Adaptor Colours	OM3: AQUA ; OM4 VIOLET ; SM BLUE	
Assemblies	Pre_installed male MTP®/MPO to fanout LC assemblies inside module	
Performance	Insert Loss(MTP®/MPO+LC)	Return Loss (per fiber)
SM	0.75dB(standard)	55dB
	0.5dB(Low Loss)	
MM	0.5dB(standard),	26dB
	0.35dB(Low Loss)	
Durability	500 mating	
Installation temperature	0°C to +60°C	
Operating Temperature	-20°C to +70°C	
Storage & Shipping Temperature	-40°C to +75°C	

UCCONNECT[®] UC9500 High Density Fibre Suite

Construction

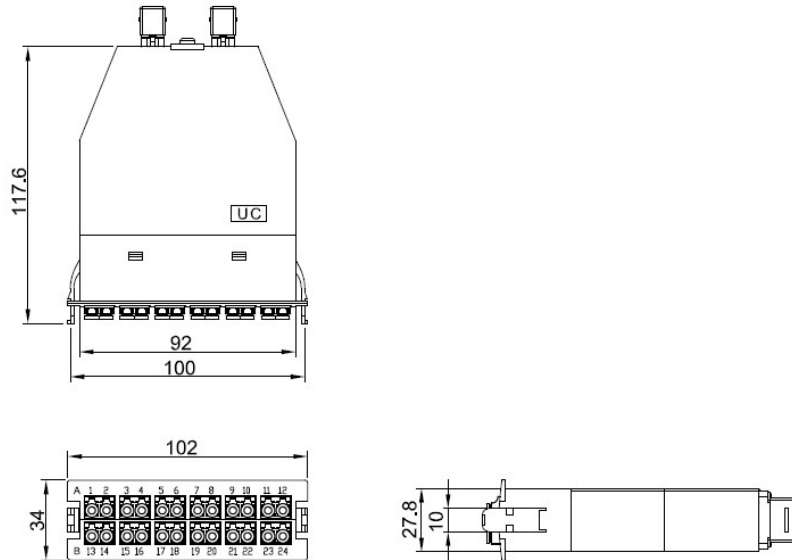

Ordering Information

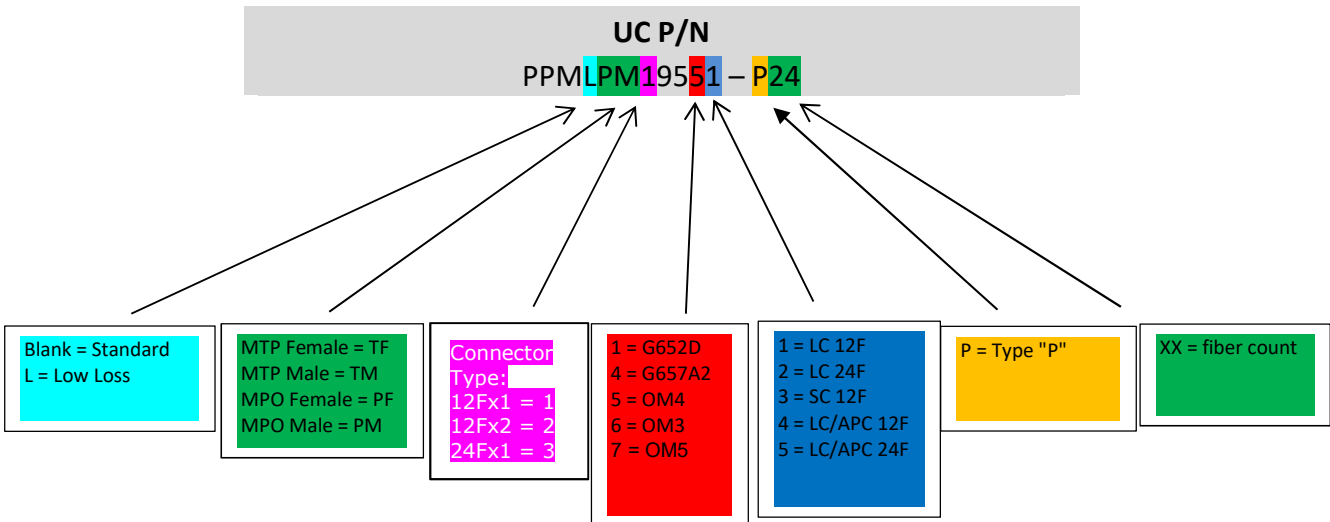

UCCONNECT®

UC9500 High Density Fibre Suite

SAP1C	UC P/N	Material Description	Weight	Item per Packing Unit
		<u>Type "P"</u>		
na	PPMPM19541-P12	UC9500 Module MPO-Duplex LC 12F G657A2 Blue Type P	126g	1
na	PPMLPM19541-P12	UC9500 Module Low Loss MPO-Duplex LC 12F G657A2 Blue Type P	126g	1
na	PPMTM29542-P24	UC9500 Module MTP-Duplex LC 24F G657A2 Blue Type P	140g	1
na	PPMPM29542-P24	UC9500 Module MPO-Duplex LC 24F G657A2 Blue Type P	140g	1
na	PPMLPM29542-P24	UC9500 Module Low loss MPO-Duplex LC 24F G657A2 Blue Type P	140g	1
na	PPMTM19551-P12	UC9500 Module MTP-Duplex LC 12F OM4 Violet Type P	126g	1
na	PPMPM19551-P12	UC9500 Module MPO-Duplex LC 12F OM4 Violet Type P	126g	1
na	PPMLPM19551-P12	UC9500 Module Low Loss MPO-Duplex LC 12F OM4 Violet Type P	126g	1
na	PPMTM29552-P24	UC9500 Module MTP-Duplex LC 24F OM4 Violet Type P	140g	1
na	PPMPM29552-P24	UC9500 Module MPO-Duplex LC 24F OM4 Violet Type P	140g	1
na	PPMLPM29552-P24	UC9500 Module Low Loss MPO-Duplex LC 24F OM4 Violet Type P	140g	1
na	PPMTM19561-P12	UC9500 Module MTP-Duplex LC 12F OM3 Aqua Type P	126g	1
na	PPMPM19561-P12	UC9500 Module MPO-Duplex LC 12F OM3 Aqua Type P	126g	1
na	PPMLPM19561-P12	UC9500 Module Low Loss MPO-Duplex LC 12F OM3 Aqua Type P	126g	1
na	PPMTM29562-P24	UC9500 Module MTP-Duplex LC 24F OM3 Aqua Type P	140g	1
na	PPMPM29562-P24	UC9500 Module MPO-Duplex LC 24F OM3 Aqua Type P	140g	1
na	PPMLPM29562-P24	UC9500 Module Low Loss MPO-Duplex LC 24F OM3 Aqua Type P	140g	1

Enquiries

Please contact our local sales office or mms.asia@prysmiangroup.com

Multimedia Solutions is the data communication portfolio of Prysmian Group and comprises all the necessary portfolio of cable solutions for data communication.

Ask about UCCONNECT® for a complete Structured Cabling Solution with 25 Years System Warranty.

Visit www.DrakaUC.com for more information.

PrysmianGroup 2019, All Rights Reserved

All sizes and values without tolerances are reference values. Specifications are for product as supplied by PrysmianGroup: any modification or alteration afterwards of product may give different result.

The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of PrysmianGroup. The information is believed to be correct at the time of issue. PrysmianGroup reserves the right to amend this specification without prior notice. This specification is not contractually valid unless specifically authorized by PrysmianGroup.